



CT250800Q0, Tie, 8.43" Max Bundle, 250 Lb Tensile, UV Black

By Burndy
Catalog # [CT250800Q0](#)

Nylon UNIRAP™ Cable Tie - 250 Lb. Tensile Strength, UV Black, Nylon 6/6, 28.7" Long, 25 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.000 in
Length	28.7 in
Package Weight	0.000 lb.
Dimension - Width mm	13 mm
Dimension - Width inch	0.50 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	729 mm
Width	0.5 in
Dimension - Length Overall inch	28.70 in

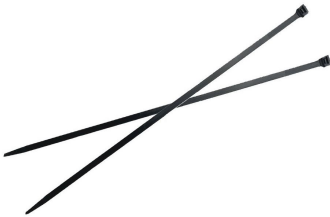

Dimension - Bundle Diameter Max inch	8.43 in
--------------------------------------	---------

Force Related

Rating - Minimum Tensile Strength lbs	250
---------------------------------------	-----

General

Color	UV Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Heavy
UPC	781810334652
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810334652

Logistics

Minimum Pack Quantity	25
Carton Quantity	500
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)