




CT30125C, Tie, 1.25" Max Bundle, 30 Lb Tensile, Natural

By Burndy
Catalog # [CT30125C](#)

Nylon UNIRAP™ Cable Tie - 30 Lb. Tensile Strength, Natural Color, 30 Lb. Tensile, 1.25" Max Bundle

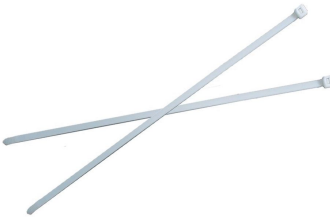

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-5-9
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	Yes
Certification - CSA Approved	No
Certification - 94VO Rated	N

Dimensions

Package Height	1.400 in
Package Weight	0.170 lb.
Package Length	10.600 in
Package Width	6.200 in
Dimension - L Length Overall mm	148 mm
Length	6 in
Dimension - Width mm	4 mm

Dimension - Width inch	0.14 in
Dimension - Length Overall inch	5.84 in
Dimension - Bundle Diameter Max inch	1.40 in

Force Related

Rating - Minimum Tensile Strength lbs	30
---------------------------------------	----

General

Tool Type	Intermediate
Military Specification	MS3367
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810331804
Type	Intermediate
Material	NYLON 6/6
UPC 14 Digit GTIN	00781810331804

Logistics

Pallet Quantity	99999
Carton Quantity	10000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)