



CT30125C0UG, Tie, 1.25" Max Bundle, UV Black

By Burndy
Catalog # [CT30125C0UG](#)

Nylon UNIRAP™ Cable Tie - 30 Lb. Tensile Strength (Universal Grade), 100 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.750 in
Length	5.9 in
Package Weight	0.160 lb.
Dimension - Width mm	3 mm
Dimension - Width inch	0.13 in
Package Length	9.800 in
Package Width	5.200 in
Dimension - L Length Overall mm	150 mm
Width	0.13 in

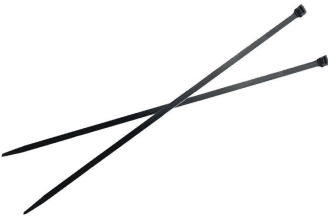

Dimension - Length Overall inch	5.90 in
Dimension - Bundle Diameter Max inch	1.25 in

Force Related

Rating - Minimum Tensile Strength lbs	30
---------------------------------------	----

General

Color	UV Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Intermediate
UPC	781810469040
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469040

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	40000

Product Assets

[Catalog \[English\]](#)