




# CT30125M, Tie, 1.25" Max Bundle, 30 Lb Tensile, Natural

By Burndy  
Catalog # CT30125M

Nylon UNIRAP™ Cable Tie - 30 Lb. Tensile Strength

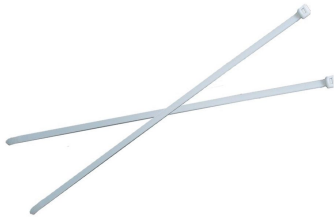

## Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

## Application

For General Purpose

## Specifications

|                                    |                               |
|------------------------------------|-------------------------------|
| Certification - UL Recognized      | No                            |
| Certification - cULus              | Yes                           |
| EU RoHS Indicator                  | Yes                           |
| Industry Standard(s)               | Military Specified (Mil-Spec) |
| Military Spec Number               | MS3367-5-9                    |
| Certification - ETL                | No                            |
| Standards - Industry Standards Met | Military Specified (Mil-Spec) |
| Standards - RoHS Compliance Status | CM                            |
| Certification - UV Rated           | No                            |
| UL Listed                          | No                            |
| Certification - CSA Approved       | No                            |
| Certification - 94VO Rated         | N                             |

## Dimensions

|                                 |           |
|---------------------------------|-----------|
| Package Height                  | 2.000 in  |
| Package Weight                  | 1.570 lb. |
| Package Length                  | 17.000 in |
| Package Width                   | 10.100 in |
| Dimension - L Length Overall mm | 146 mm    |
| Width                           | 0.14 in   |
| Length                          | 6 in      |
| Dimension - Width mm            | 3.6 mm    |

|                                      |         |
|--------------------------------------|---------|
| Dimension - Width inch               | 0.14 in |
| Dimension - Length Overall inch      | 5.75 in |
| Dimension - Bundle Diameter Max inch | 1.25    |

## Force Related

|                                       |    |
|---------------------------------------|----|
| Rating - Minimum Tensile Strength lbs | 30 |
|---------------------------------------|----|

## General

|                        |                  |
|------------------------|------------------|
| Trade Name             | UNIRAP™          |
| Military Specification | MS3367           |
| Color                  | Natural          |
| Sub Brand              | UNIRAP,CABLE TIE |
| Series                 | UNIRAP™ Series   |
| UPC                    | 781810331910     |
| Type                   | Intermediate     |
| Material               | NYLON 6/6        |
| UPC 14 Digit GTIN      | 00781810331910   |

## Logistics

|                 |       |
|-----------------|-------|
| Pallet Quantity | 99999 |
| Carton Quantity | 10000 |

## Operational

|                                   |        |
|-----------------------------------|--------|
| Operating Temperature Celcius Max | 85 °C  |
| Operating Temperature Celcius Min | -40 °C |

## Product Assets

[Catalog \[English\]](#)