




CT30125MH8M, Tie, 1.25" Max Bundle, Natural, Screw Mount

By Burndy
Catalog # [CT30125MH8M](#)

Nylon UNIRAP™ Cable Tie - 30 Lb. Tensile Strength (Screw Mount), 1000 pack

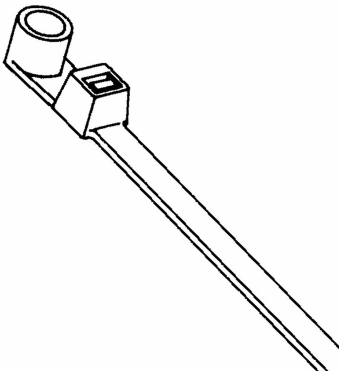

Features

- Mounting Hole

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	Yes
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Configuration

Mounting Method	Screw
-----------------	-------

Dimensions

Package Height	0.000 in
Length	5.8 in
Package Weight	0.000 lb.
Dimension - Width mm	3 mm
Dimension - Width inch	0.13 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	147 mm
Width	0.13 in
Dimension - Screw Size inch	#8
Dimension - Length Overall inch	5.80 in

Dimension - Bundle Diameter Max inch	1.25
--------------------------------------	------

Force Related

Rating - Minimum Tensile Strength lbs	30
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810335215
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810335215

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	1
Carton Quantity	10000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand