




CT40200C, Cable Tie, 2" Max Bundle, 40 Lb Tensile, Natural

By Burndy
Catalog # CT40200C

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength

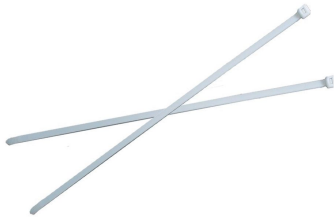

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	No
UL Listed	Yes
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.750 in
Package Weight	0.250 lb.
Package Length	13.500 in
Package Width	6.000 in
Dimension - L Length Overall mm	225 mm
Width	0.15 in
Length	8.5 in
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in

Dimension - Length Overall inch	8.87 in
Dimension - Bundle Diameter Max inch	2.00

Force Related

Rating - Minimum Tensile Strength lbs	40
---------------------------------------	----

General

Trade Name	UNIRAP™
Tool Type	Intermediate
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810331927
Type	Intermediate
Material	NYLON 6/6
UPC 14 Digit GTIN	00781810331927

Logistics

Pallet Quantity	99999
Carton Quantity	10000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)