



CT40200C0, Cable Tie, 2" Max Bundle, 40 Lb Tensile, UV Black

By Burndy
Catalog # [CT40200C0](#)

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength, UV Black, Nylon 6/6, 8.5" Long, 100 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For Outdoor Applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.750 in
Package Weight	0.250 lb.
Package Length	13.500 in
Package Width	6.000 in
Dimension - L Length Overall mm	225 mm
Width	0.15 in
Length	8.5 in
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in

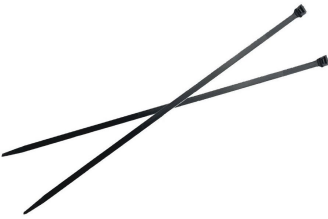

Dimension - Length Overall inch	8.87 in
Dimension - Bundle Diameter Max inch	2.00

Force Related

Rating - Minimum Tensile Strength lbs	40
---------------------------------------	----

General

Trade Name	UNIRAP™
Tool Type	Intermediate
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332382
Type	Intermediate
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332382

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	1000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand