


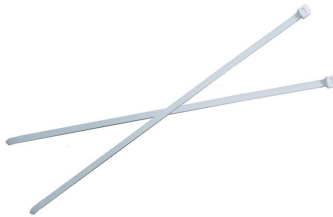

CT40200CUG, Tie, 2" Max Bundle, Natural, Universal Grade

By Burndy
Catalog # [CT40200CUG](#)

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength (Universal Grade), 100 pack



Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.800 in
Length	7.9 in
Package Weight	0.210 lb.
Dimension - Width mm	3.8 mm
Dimension - Width inch	0.15 in
Package Length	12.000 in
Package Width	4.500 in
Dimension - L Length Overall mm	201 mm
Width	0.15 in

Dimension - Length Overall inch	7.90 in
Dimension - Bundle Diameter Max inch	2.00

Force Related

Rating - Minimum Tensile Strength lbs	40
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Intermediate
UPC	781810469064
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469064

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	13000

Product Assets

[Catalog \[English\]](#)



A Hubbell brand