



CT40200M, Tie, 2.37" Max Bundle, 40 Lb
Tensile, Natural

By Burndy
Catalog # [CT40200M](#)

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	2.500 in
Length	8.87 in
Package Weight	2.290 lb.
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in
Package Length	16.000 in
Package Width	11.000 in
Dimension - L Length Overall mm	225 mm
Width	0.14 in
Dimension - Length Overall inch	8.87 in

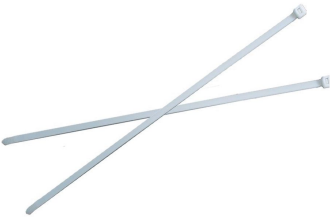

Dimension - Bundle Diameter Max 2.37 in
inch

Force Related

Rating - Minimum Tensile Strength 40
lbs

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810332030
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332030

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius	85 °C
Max	
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)