




CT40200M0, Tie, 1.25" Max Bundle, 30 Lb Tensile, UV Black

By Burndy
Catalog # [CT40200M0](#)

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength

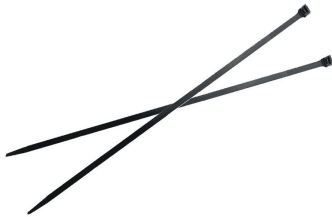

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For Outdoor Applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	2.500 in
Package Weight	2.290 lb.
Package Length	17.000 in
Package Width	10.000 in
Dimension - L Length Overall mm	225 mm
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in

Dimension - Length Overall inch	8.87 in
Dimension - Bundle Diameter Max inch	2.37 in

Force Related

Rating - Minimum Tensile Strength lbs	40
---------------------------------------	----

General

Trade Name	UNIRAP™
Color	Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332399
Type	Intermediate
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332399

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	5000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)