




CT40200M00, Tie, 2.37" Max Bundle, 40 Lb Tensile, UV Black

By Burndy
Catalog # [CT40200M00](#)

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength

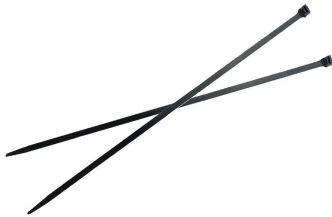

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.000 in
Length	8.87 in
Package Weight	0.000 lb.
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	225 mm
Width	0.14 in
Dimension - Length Overall inch	8.87 in

Dimension - Bundle Diameter 2.37 in
Max inch

Force Related

Rating - Minimum Tensile Strength lbs 40

General

Color	Black
Series	UNIRAP™ Series
UPC	781810332337
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332337

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	1
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand