




CT40300M, Tie, 3.37" Max Bundle, 40 Lb Tensile, Natural

By Burndy
Catalog # [CT40300M](#)

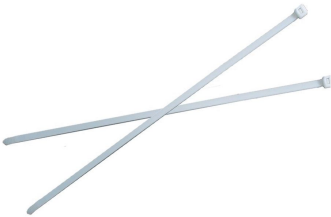

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	3.000 in
Length	10.96 in
Package Weight	3.560 lb.
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in
Package Length	17.000 in
Package Width	11.500 in
Dimension - L Length Overall mm	278 mm
Width	0.14 in
Dimension - Length Overall inch	10.96 in

Dimension - Bundle Diameter Max inch	3.37 in
--------------------------------------	---------

Force Related

Rating - Minimum Tensile Strength lbs	40
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810332153
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332153

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)