




CT40400C00, Tie, 4" Max Bundle, 40 Lb Tensile, UV Black

By Burndy
Catalog # [CT40400C00](#)

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength, UV Black, Nylon 6/6, 14.25" Long, 100 pack

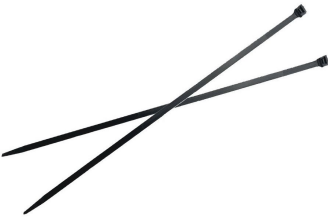

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.000 in
Length	14.25 in
Package Weight	0.000 lb.
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	362 mm
Width	0.18 in
Dimension - Length Overall inch	14.25 in

Dimension - Bundle Diameter Max inch	4.00
--------------------------------------	------

Force Related

Rating - Minimum Tensile Strength lbs	40
---------------------------------------	----

General

Color	UV Black (Mil. Spec.)
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Intermediate
UPC	781810332368
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332368

Logistics

Minimum Pack Quantity	100
Pallet Quantity	1
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)