




CT40400M0, Cable Tie, 4" Max Bundle, 40 Lb Tensile, UV Black

By Burndy
Catalog # [CT40400M0](#)

Nylon UNIRAP™ Cable Tie - 40 Lb. Tensile Strength

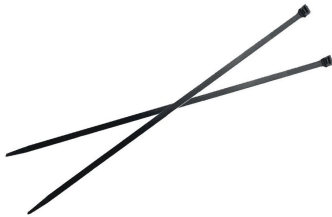

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Length	14.25 in
Dimension - Width mm	4 mm
Dimension - Width inch	0.14 in
Dimension - L Length Overall mm	362 mm
Width	0.14 in
Dimension - Length Overall inch	14.25 in
Dimension - Bundle Diameter Max inch	4

Force Related

Rating - Minimum Tensile Strength lbs	40
---------------------------------------	----

General

Color	Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810332436
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332436

Logistics

Minimum Pack Quantity	1000
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)