


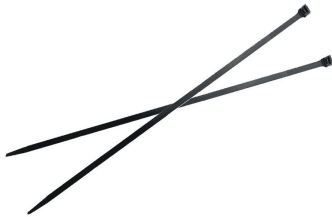

CT50175C0, Cable Tie, 4" Max Bundle, 50 Lb Tensile, Black

By Burndy
Catalog # [CT50175C0](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength



Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For Outdoor Applications

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Military Spec Number	MS3367-1-0
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	Yes
UL Listed	Yes
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	0.800 in
Package Weight	0.290 lb.
Package Length	12.500 in
Package Width	6.000 in
Dimension - L Length Overall mm	192 mm
Length	8 in
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in

Dimension - Length Overall inch	7.56 in
Dimension - Bundle Diameter Max inch	1.87 in

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Trade Name	UNIRAP™
Tool Type	Standard
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332863
Type	Standard
Material	NYLON 6/6
UPC 14 Digit GTIN	00781810332863

Logistics

Pallet Quantity	99999
Carton Quantity	10000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)