




CT50175C6, Cable Tie, 1.75" Max Bundle, 50 Lb Tensile, Blue

By Burndy
Catalog # [CT50175C6](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, Blue, Nylon 6/6, 8" Long, 100 pack

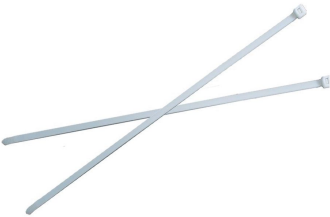

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-1-6
Certification - 94V0 Rated	N

Dimensions

Package Height	0.600 in
Length	7.56 in
Package Weight	0.300 lb.
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Package Length	12.750 in
Package Width	6.000 in
Dimension - L Length Overall mm	192 mm
Width	0.18 in
Dimension - Length Overall inch	7.56 in

Dimension - Bundle Diameter Max inch	1.875
--------------------------------------	-------

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Blue
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810332504
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332504

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)