



CT50175C8, Cable Tie, 1.75" Max Bundle, 50 Lb Tensile, Gray

By Burndy
Catalog # [CT50175C8](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, Gray, Nylon 6/6, 8" Long, 100 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-1-8
Certification - 94V0 Rated	N

Dimensions

Length	7.56 in
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Dimension - L Length Overall mm	192 mm
Width	0.18 in
Dimension - Length Overall inch	7.56 in
Dimension - Bundle Diameter Max inch	1.875

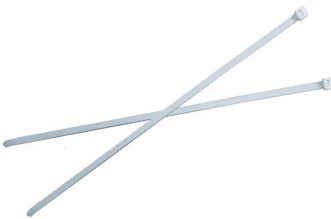

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Gray
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810332528
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332528

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)