


CT50175CUG, Tie, 50 Lb Tensile, Natural, Universal Grade

By Burndy
Catalog # [CT50175CUG](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Universal Grade), 100 pack

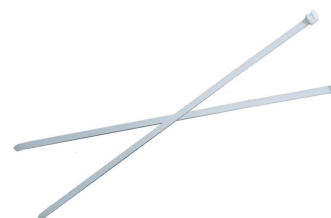

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	0.800 in
Length	8 in
Package Weight	0.280 lb.
Dimension - Width mm	4.6 mm
Dimension - Width inch	0.18 in
Package Length	12.000 in
Package Width	5.400 in

Dimension - L Length Overall mm	199 mm
Width	0.18 in
Dimension - Length Overall inch	7.83 in
Dimension - Bundle Diameter Max inch	1.75

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810469071
Type	UG, Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469071

Logistics

Minimum Pack Quantity	100
Pallet Quantity	18000
Carton Quantity	9000

Product Assets

[Catalog \[English\]](#)