




CT50175M0, Tie, 1.75" Max Bundle, 50 Lb Tensile, UV Black 1

By Burndy
Catalog # CT50175M0

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength

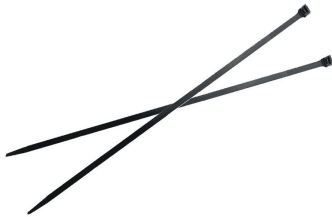

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For Outdoor Applications

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UV Rated	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-1-0
Certification - 94VO Rated	N

Dimensions

Package Height	2.750 in
Length	8 in
Package Weight	2.830 lb.
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Package Length	17.750 in
Package Width	12.000 in
Dimension - L Length Overall mm	192 mm

Width	0.18 in
Dimension - Length Overall inch	7.56 in
Dimension - Bundle Diameter Max inch	1.875

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Black
Trade Name	UNIRAP™
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332870
Type	Standard
Material	NYLON 6/6
Military Specification	MS3367
UPC 14 Digit GTIN	00781810332870

Logistics

Pallet Quantity	99999
Carton Quantity	10000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)