



CT50175MH10CUG, Tie, 1.75" Max Bundle, Natural, Screw Mount

By Burndy
Catalog # [CT50175MH10CUG](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Universal Grade), 100 pack

Features


- Mounting Hole

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	1.250 in
Length	7.79 in
Package Weight	0.320 lb.
Dimension - Width mm	4.6 mm
Dimension - Width inch	0.18 in
Package Length	12.000 in
Package Width	5.300 in
Dimension - L Length Overall mm	198 mm
Width	0.18 in
Dimension - Screw Size inch	#10

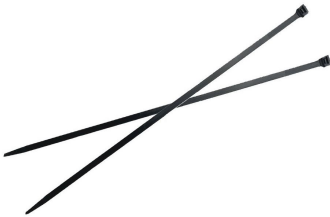

Dimension - Length Overall inch	7.79 in
Dimension - Bundle Diameter Max inch	1.75

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810469194
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469194

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	10000

Product Assets

[Catalog \[English\]](#)



A Hubbell brand