




CT50175MH10M, Tie, 1.75" Max Bundle, Natural, Screw Mount

By Burndy
Catalog # [CT50175MH10M](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Screw Mount), 1000 pack

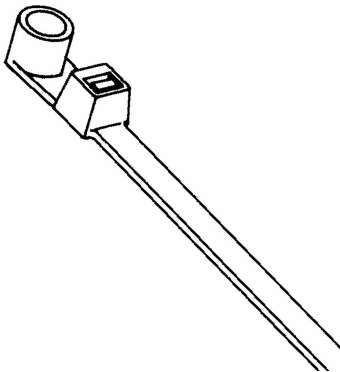

Features

- Mounting Hole

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	Yes
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Configuration

Mounting Method	Screw
-----------------	-------

Dimensions

Package Height	3.000 in
Length	8 in
Package Weight	3.350 lb.
Dimension - Width mm	4 mm
Dimension - Width inch	0.17 in
Package Length	16.000 in
Package Width	11.750 in
Dimension - L Length Overall mm	203 mm
Width	0.17 in
Dimension - Screw Size inch	#10
Dimension - Length Overall inch	8.00 in

Dimension - Bundle Diameter Max inch	1.75 in
--------------------------------------	---------

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810335253
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810335253

Logistics

Minimum Pack Quantity	5000
Pallet Quantity	99999
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)