




CT50175MUG, Tie, 1.75" Max Bundle, Natural, Universal Grade

By Burndy
Catalog # [CT50175MUG](#)

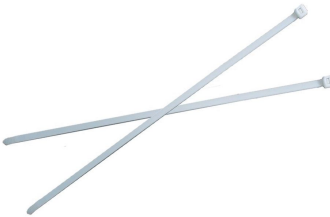

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Universal Grade), 1000 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	1.750 in
Length	7.83 in
Package Weight	2.600 lb.
Dimension - Width mm	4.6 mm
Dimension - Width inch	0.18 in
Package Length	14.750 in
Package Width	11.500 in
Dimension - L Length Overall mm	199 mm
Width	0.18 in

Dimension - Length Overall inch	7.83 in
Dimension - Bundle Diameter Max inch	1.75 in

Force Related

Rating - Minimum Tensile Strength lbs	50 Lb
---------------------------------------	-------

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810469088
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469088

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	11000

Product Assets

[Catalog \[English\]](#)