




CT50300C, Cable Tie, 3" Max Bundle, 50 Lb Tensile, Natural

By Burndy
Catalog # CT50300C

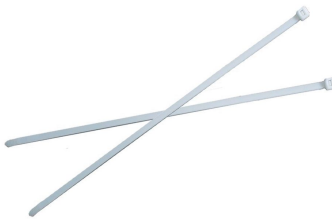

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-7-9
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94VO Rated	N

Dimensions

Package Height	1.250 in
Package Weight	0.430 lb.
Package Length	16.000 in
Package Width	6.000 in
Dimension - L Length Overall mm	286 mm
Length	11.75 in
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in

Dimension - Length Overall inch	11.25
Dimension - Bundle Diameter Max inch	3.00

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Trade Name	UNIRAP™
Tool Type	Standard
Military Specification	MS3367
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332566
Type	Standard
Material	NYLON 6/6
UPC 14 Digit GTIN	00781810332566

Logistics

Pallet Quantity	99999
Carton Quantity	5000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand