




CT50300C0, Cable Tie, 3" Max Bundle, 50 Lb Tensile, UV Black

By Burndy

Catalog # [CT50300C0](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, UV Black, Nylon 6/6, 11.75" Long, 100 pack

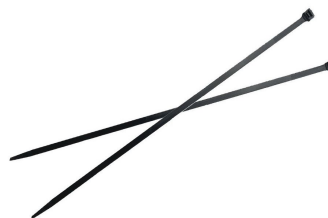

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For Outdoor Applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-7-0
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Dimensions

Package Height	1.000 in
Package Weight	0.410 lb.
Package Length	17.000 in
Package Width	5.750 in
Dimension - L Length Overall mm	286 mm
Length	11.75 in
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in

Dimension - Length Overall 11.25 in

Dimension - Bundle Diameter 3.00 Max inch

Force Related

Rating - Minimum Tensile Strength lbs 50

General

Trade Name	UNIRAP™
Tool Type	Standard
Military Specification	MS3367
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332887
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332887

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	5000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand