



CT50300C00, Tie, 3" Max Bundle, 50 Lb Tensile, UV Black

By Burndy
Catalog # [CT50300C00](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, UV Black, Nylon 6/6, 11.25" Long, 100 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-7-0
Certification - 94V0 Rated	N

Dimensions

Package Height	0.750 in
Length	11.25 in
Package Weight	0.420 lb.
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Package Length	17.000 in
Package Width	6.000 in
Dimension - L Length Overall mm	286 mm
Width	0.18 in
Dimension - Length Overall inch	11.25 in

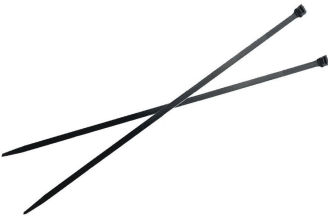

Dimension - Bundle Diameter Max inch	3.00
--------------------------------------	------

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	UV Black (Mil. Spec.)
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810332825
Material	Nylon 6/6
Military Specification	MS3367
UPC 14 Digit GTIN	00781810332825

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand