




CT50300MH10COUG, Tie, 50 Lb Tensile, UV Black, Screw Mount

By Burndy
Catalog # [CT50300MH10COUG](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Universal Grade), 100 pack

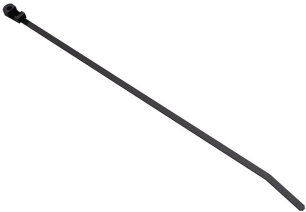

Features

- Mounting Hole

Specifications

Standards - RoHS Compliance Status	CM
UL Listed	Yes
Certification - CSA Approved	Yes

Dimensions

Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Dimension - L Length Overall mm	298 mm
Depth	2.125 in
Dimension - Screw Size inch	#10
Dimension - Length Overall inch	11.73 in
Dimension - Bundle Diameter Max inch	3.00

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Black
Series	UNIRAP™ Series
Tool Type	Standard
Volume	30
UPC	781810655566
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810655566

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	35
Carton Quantity	5000

Product Assets

[Catalog \[English\]](#)