


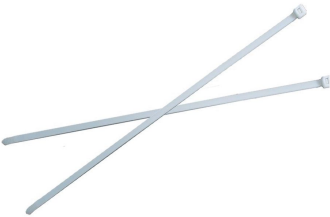

CT50300MUG, Tie, 3" Max Bundle, Natural, Universal Grade

By Burndy
Catalog # [CT50300MUG](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Universal Grade), 1000 pack



Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	2.300 in
Length	11.34 in
Package Weight	4.020 lb.
Dimension - Width mm	4.6 mm
Dimension - Width inch	0.18 in
Package Length	17.000 in
Package Width	14.000 in
Dimension - L Length Overall mm	288 mm
Width	0.18 in
Dimension - Length Overall inch	11.34 in

Dimension - Bundle Diameter Max 3 inch

Force Related

Rating - Minimum Tensile Strength	50 N
Rating - Minimum Tensile Strength	50 Lb lbs

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810469095
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469095

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	5000

Product Assets

[Catalog \[English\]](#)