



CT50400C0, Cable Tie, 4" Max Bundle, 50 Lb Tensile, UV Black

By Burndy
Catalog # [CT50400C0](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, UV Black 1, Nylon 6/6, 15.5" Long, 100 pack

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application


For Outdoor Applications

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	TAA Compliant (All status valid till December 2026)
Military Spec Number	MS3367-2-0
Certification - ETL	No
Standards - RoHS Compliance Status	CM
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No
Certification - 94VO Rated	N

Dimensions

Package Height	1.250 in
Package Weight	0.530 lb.
Package Length	19.500 in
Package Width	6.000 in
Dimension - L Length Overall mm	362 mm
Length	15.5 in
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in

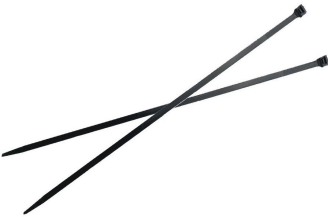

Dimension - Length Overall inch	14.25 in
Dimension - Bundle Diameter Max inch	4.00

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Trade Name	UNIRAP™
Tool Type	Standard
Color	UV Black
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810332900
Type	Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332900

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	5000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)