



CT50400C0UG, Tie, 4" Max Bundle, UV Black, Universal Grade

By Burndy
Catalog # [CT50400C0UG](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Universal Grade), 100 pack

Features


- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	Yes
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	1.200 in
Length	14.6 in
Package Weight	0.510 lb.
Dimension - Width mm	4.6 mm
Dimension - Width inch	0.18 in
Package Length	19.000 in
Package Width	5.400 in
Dimension - L Length Overall mm	371 mm
Width	0.18 in

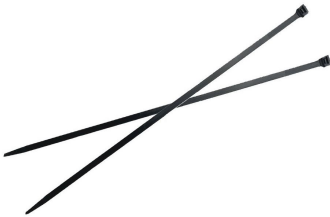

Dimension - Length Overall inch	14.60 in
Dimension - Bundle Diameter Max inch	4.00

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	UV Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810469163
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469163

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	12000

Product Assets

[Catalog \[English\]](#)