




CT50400C2, Cable Tie, 4" Max Bundle, 50 Tensile, Red

By Burndy
Catalog # [CT50400C2](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength

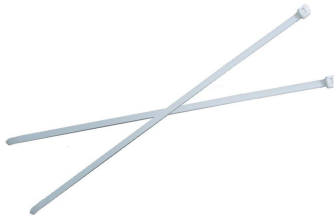

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	UI
Certification - cULus	No
Certification - UV Rated	No
UL Listed	Yes
Certification - CSA Approved	No
Military Spec Number	MS3367-2-2
Certification - 94V0 Rated	N

Dimensions

Package Height	0.750 in
Length	14.25 in
Package Weight	0.530 lb.
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Package Length	18.750 in
Package Width	6.200 in
Dimension - L Length Overall mm	362 mm
Width	0.18 in
Dimension - Length Overall inch	14.25 in

Dimension - Bundle Diameter Max inch 4

Force Related

Rating - Minimum Tensile Strength lbs 50

General

Color	Red
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810332702
Material	NYLON 6/6
UPC 14 Digit GTIN	00781810332702

Logistics

Pallet Quantity	99999
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)