


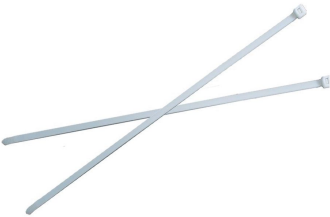

CT50400C3, Cable Tie, 4" Max Bundle, 50 Tensile, Orange

By Burndy
Catalog # [CT50400C3](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength, Orange,
Nylon 6/6, 14.25" Long, 100 pack



Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Military Spec Number	MS3367-2-3
Certification - 94V0 Rated	N

Dimensions

Length	14.25 in
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Dimension - L Length Overall mm	362 mm
Width	0.18 in
Dimension - Length Overall inch	14.25 in
Dimension - Bundle Diameter Max inch	4

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Orange
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810332719
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810332719

Logistics

Minimum Pack Quantity	5000
Pallet Quantity	99999
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)