




CT50400CUG, Tie, 50 Lb Tensile, Natural, Universal Grade

By Burndy

Catalog # [CT50400CUG](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Universal Grade), 100 pack

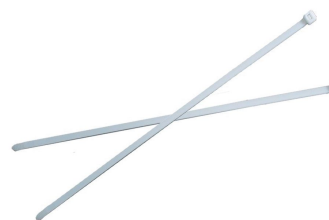

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - ETL	No
Certification - UL Recognized	Yes
Standards - RoHS Compliance Status	CM
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No

Dimensions

Package Height	1.300 in
Length	15.5 in
Package Weight	0.520 lb.
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Package Length	18.500 in
Package Width	5.250 in

Dimension - L Length Overall mm	371 mm
Width	0.18 in
Dimension - Length Overall inch	14.60 in
Dimension - Bundle Diameter Max inch	4.00

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
Tool Type	Standard
UPC	781810469118
Type	UG, Standard
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810469118

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	12000

Product Assets

[Catalog \[English\]](#)



A Hubbell brand