


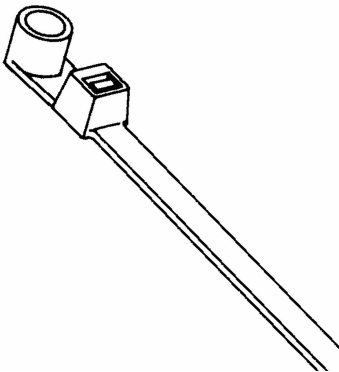

CT50400MH10C, Tie, 4" Max Bundle, Natural, Screw Mount

By Burndy
Catalog # [CT50400MH10C](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Screw Mount), 100 pack



Features

- Mounting Hole

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94V0 Rated	N

Configuration

Mounting Method	Screw
-----------------	-------

Dimensions

Package Height	1.000 in
Length	14.5 in
Package Weight	0.570 lb.
Dimension - Width mm	5 mm
Dimension - Width inch	0.18 in
Package Length	19.250 in
Package Width	6.000 in
Dimension - L Length Overall mm	368 mm
Width	0.17 in
Dimension - Screw Size inch	#10
Dimension - Length Overall inch	14.50 in

Dimension - Bundle Diameter Max inch	4.00
--------------------------------------	------

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Natural
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810335284
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810335284

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	1000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)