



CT50400RC0, Cable Tie, 4" Max Bundle, UV Black, Releasable

By Burndy
Catalog # [CT50400RC0](#)

Nylon UNIRAP™ Cable Tie - 50 Lb. Tensile Strength (Releasable), 100 pack

Features


- Releasable Cable Tie
- Specially suitable for prototype construction or temporary installation
- Also suitable where service often requires adding or subtracting wires from an existing bundle

Specifications

Standards - RoHS Compliance	CM
Status	
Certification - UV Rated	Yes
Certification - CSA Approved	No

Dimensions

Package Height	0.000 in
Length	14.6 in
Package Weight	0.000 lb.
Dimension - Width mm	4.6 mm
Dimension - Width inch	0.18 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	371 mm
Width	0.18 in
Dimension - Length Overall inch	14.60 in
Dimension - Bundle Diameter Max inch	4.00

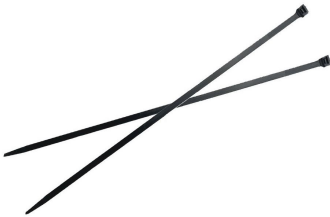

Force Related

Rating - Minimum Tensile Strength lbs	50
---------------------------------------	----

General

Color	Black
Trade Name	UNIRAP™
Series	UNIRAP™ Series
UPC	781810334744
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810334744

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	1
Carton Quantity	5000
Packaging Type	Bag

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)



A Hubbell brand