



# CTNT50725D0, Tie, 7.3" Max Bundle, Black, Nylon 12

By Burndy  
Catalog # [CTNT50725D0](#)

Nylon 12 UNIRAP™ Cable Tie - 50 Lb. Tensile Strength

## Features


- Nylon 12 Cable Ties provide excellent UV, chemical and moisture resistant
- Ties feature inside serrations and bent tail for quick, easy installation
- Smooth edge to prevent bundle damage
- Especially suitable in high moisture, corrosive (zinc chloride and dilute acids) environments
- Good in low temperatures
- Indoor/Outdoor applications

## Specifications

|                              |    |
|------------------------------|----|
| Standards - RoHS Compliance  | CM |
| Status                       |    |
| Certification - CSA Approved | No |

## Dimensions

|                                 |          |
|---------------------------------|----------|
| Width                           | 0.19 in  |
| Length                          | 25.6 in  |
| Thickness                       | 0.06 in  |
| Dimension - Width mm            | 4.8 mm   |
| Dimension - Width inch          | 0.19 in  |
| Dimension - Length Overall inch | 25.60 in |

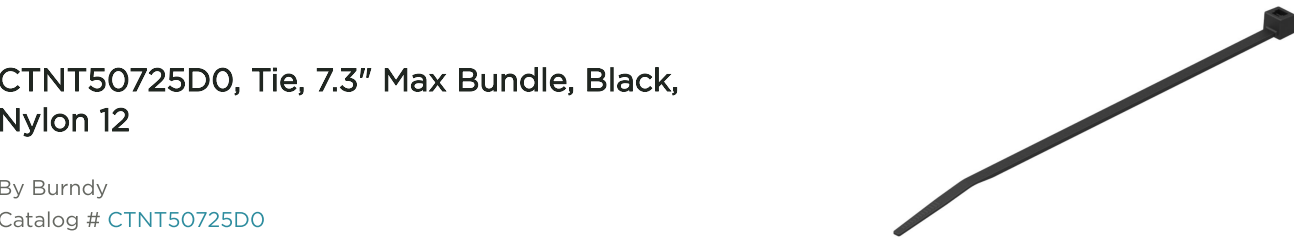

|                                      |         |
|--------------------------------------|---------|
| Dimension - L Length Overall mm      | 650 mm  |
| Dimension - Bundle Diameter Max inch | 7.30 in |

## Force Related

|                                       |                |
|---------------------------------------|----------------|
| Tensile Strength                      | 50 / 22 lb./Kg |
| Rating - Minimum Tensile Strength lbs | 50 lb          |

## General

|            |                |
|------------|----------------|
| Color      | Black          |
| UPC        | 621945469402   |
| Trade Name | UNIRAP™        |
| Material   | Nylon 12       |
| Series     | UNIRAP™ Series |

## Logistics

|                       |      |
|-----------------------|------|
| Minimum Pack Quantity | 500  |
| Carton Quantity       | 5000 |

## Product Assets

[Catalog \[English\]](#)