




CY4CL72G5TN Rope Lay Braid

By Burndy
Catalog # [CY4CL72G5TN](#)

Rope Lay Braid

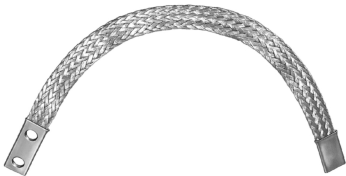

Features

- Most Burndy braid are UL Listed and CSA Certified
- Pressed seamless copper ferrules provide added durability and prevent fraying, providing extra strength for a robust bonding connection
- Braid is especially suited for applications that require flexibility or resistance to vibration
- Extra fine stranding gives enhanced flexibility
- Ferrules clearly marked with Burndy braid type and UL markings (where appropriate)
- Available in custom lengths and hole sizes to suit your needs (contact your local sales representative for non-standard configurations)
- For assistance in finding the perfect braid for your needs click [here](#) for our Braid Configurator Tool:
www.hubbell.com/config/BRAID

Specifications

Certification - CSA Approved No

Configuration

Connector Type Braid

Dimensions

Package Height	0.000 in
Length	72 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in

General

UPC	621945436640
Material	Copper
UPC 12 Digit	621945436640
UPC 14 Digit GTIN	00621945436640

Logistics

Minimum Pack Quantity	1
Pallet Quantity	720
Carton Quantity	5

Product Assets

[Catalog \[English\]](#)