




DUW44, Deadend Clamp, 500-1000 kcmil Copper

By Burndy
Catalog # [DUW44](#)

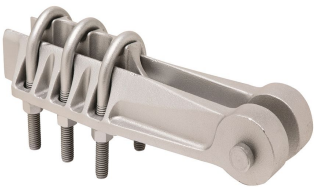

Cu Deadend clamp, 500-1000 kcmil

Features

- High strength, corrosion resistant copper alloy strain clamp
- Three silicon bronze U-bolts
- Single serrated saddle
- Galvanized steel clevis pin

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	500 kcmil-1000 kcmil
Conductor - Copper Str Size	• 500 kcmil • 550 kcmil • 600 kcmil • 700 kcmil • 750 kcmil • 800 kcmil • 850 kcmil • 900 kcmil • 1000 kcmil

Configuration

Connector Type	Deadend
----------------	---------

Dimensions

Package Height	0.000 in
Dimension - Height mm	71.4 mm
Dimension - Height inch	2.81 in
Dimension - Height fraction	2-64/79 in
Dimension - B Length fraction	5-1/4 in
Package Weight	0.000 lb.
Dimension - Width mm	82 mm
Dimension - Width inch	3.22 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	290 mm
Dimension - B Length inch	5.25 in
Dimension - Width fraction	3-11/50 in
Dimension - Length Overall inch	11.43 in

General

Plated	Y
Material - Hardware	Galvanized Steel
UPC	781810013458
Material	Copper Alloy
Plating Type	Bright Dipped
UPC 14 Digit GTIN	00781810013458

Logistics

Minimum Pack Quantity	10
Pallet Quantity	210
Carton Quantity	2

Product Assets

[Catalog \[English\]](#)