


DUW44A, Deadend Strain Clamp without Pulling Eye, Aluminum Alloy

By Burndy

Catalog # [DUW44A](#)

Al Alloy Deadend Strain Clamp, Without Pulling Eye, 500 - 1000 kcmil Al, 397.5 - 900 kcmil ACSR

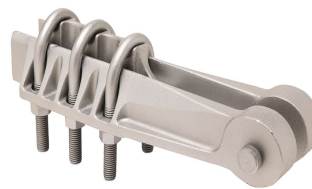

Features

- High strength cast aluminum alloy clamp recommended for strain bus applications
- Three galvanized steel U-bolts, single saddle, and headed clevis pin provide high holding strength

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AAAC 5005 Size Range	465.4 (19) kcmil-927.2 (37) kcmil
Conductor - AAAC 6201 Size Range	465.4 (19) kcmil-927.2 (37) kcmil
Conductor - AAAC 6201 Size	• 465.4 (19) kcmil • 559.5 (19) kcmil • 652.4 (19) kcmil • 740.8 (37) kcmil • 927.2 (37) kcmil
Conductor - AL Str Size	• 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil • 636 kcmil • 650 kcmil • 700 kcmil • 715 kcmil • 750 kcmil • 795 kcmil • 800 kcmil • 874 kcmil • 900 kcmil • 954 kcmil • 1000 kcmil
Conductor - AAAC 5005 Size	• 465.4 (19) kcmil • 559.5 (19) kcmil • 652.4 (19) kcmil • 740.8 (37) kcmil • 927.2 (37) kcmil

Conductor - AL Str Size Range

Conductor - ACSR Str Size

500 kcmil-1000 kcmil

- 397.5 (30/7) Larkspur kcmil
- 477.0 (18/1) Pelican kcmil
- 477.0 (24/7) Flicker kcmil
- 477.0 (26/7) Hawk kcmil
- 477. (30/7) Hen kcmil
- 500.0 (30/7) Heron kcmil
- 556.5 (24/7) Parakeet kcmil
- 556.5 (26/7) Dove kcmil
- 556.5 (30/7) Eagle kcmil
- 605 (24/7) Peacock kcmil
- 605 (26/7) Squab kcmil
- 605 (30/19) Teal kcmil
- 636 (24/7) Rook kcmil
- 636 (26/7) Grosbeak kcmil
- 636 (30/19) Egret kcmil
- 666.6 (24/7) Flamingo kcmil
- 715.5 (54/7) Crow kcmil
- 715.5 (24/7) Stilt kcmil
- 715.5 (26/7) Starling kcmil
- 715.5 (30/19) Redwing kcmil
- 795 (54/7) Condor kcmil
- 795 (26/7) Drake kcmil
- 795 (30/19) Mallard kcmil
- 874.5 (54/7) Crane kcmil
- 900 (54/7) Canary kcmil

Conductor - ACSR Str Size Range

397.5 (30/7) Larkspur kcmil-900 (54/7) Canary kcmil

Configuration

Connector Type	Deadend
----------------	---------

Dimensions

Package Height	0.000 in
Dimension - Height mm	117.1 mm
Dimension - Hole Size fraction	1-1/4
Dimension - Height inch	4.61 in
Dimension - Height fraction	3-3/8
Dimension - B Length fraction	6-4/21 in
Package Weight	0.000 lb.
Dimension - Width mm	90 mm
Dimension - Width inch	3.56 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - Z inch	2.94 in

Dimension - L Length Overall mm	314 mm	Prefilled Oxide Inhibitor	N
Dimension - B Length inch	6.19 in	Material	Aluminum Alloy
Dimension - Width fraction	3-5/8 in	Plating Type	Unplated
Dimension - Hole Size mm	32 mm	UPC 14 Digit GTIN	00781810013359
Dimension - Hole Size inch	1.25 in		
Dimension - Length Overall inch	12.38 in		
General		Logistics	
Plated	N	Minimum Pack Quantity	1
Material - Hardware	Galvanized Steel	Pallet Quantity	1
UPC	781810013359	Carton Quantity	1
		Product Assets	
		Catalog [English]	



A Hubbell brand