




DUW44AE, Deadend Strain Clamp with Pulling Eye, Aluminum Alloy

By Burndy
Catalog # [DUW44AE](#)

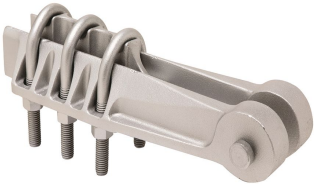

Al Alloy Deadend Strain Clamp, With Pulling Eye, 500 - 1000 kcmil Al, 397.5 - 900 kcmil ACSR

Features

- High strength cast aluminum alloy clamp recommended for strain bus applications
- Three galvanized steel U-bolts, single saddle, and headed clevis pin provide high holding strength
- Type DUW-A-E has a pulling-eye in line with conductor for easier installation

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - AAAC 5005 Size Range	465.4 (19) kcmil-927.2 (37) kcmil
Conductor - AAAC 6201 Size Range	465.4 (19) kcmil-927.2 (37) kcmil
Conductor - AAAC 6201 Size	• 465.4 (19) kcmil • 559.5 (19) kcmil • 652.4 (19) kcmil • 740.8 (37) kcmil • 927.2 (37) kcmil
Conductor - AL Str Size	• 500 kcmil • 550 kcmil • 556 kcmil • 600 kcmil • 636 kcmil • 650 kcmil • 700 kcmil • 715 kcmil • 750 kcmil • 795 kcmil • 800 kcmil • 874 kcmil • 900 kcmil • 954 kcmil • 1000 kcmil
Conductor - AAAC 5005 Size	• 465.4 (19) kcmil • 559.5 (19) kcmil • 652.4 (19) kcmil

Conductor - AL Str Size Range	500 kcmil-1000 kcmil
Conductor Type	• AAAC C 5005-Size • AAAC C 6201-Size • ACSR C Str-Size • AL C Str-Size
Conductor - ACSR Str Size	• 397.5 (30/7) Larkspur kcmil • 477.0 (18/1) Pelican kcmil • 477.0 (24/7) Flicker kcmil • 477.0 (26/7) Hawk kcmil • 477. (30/7) Hen kcmil • 500.0 (30/7) Heron kcmil • 556.5 (24/7) Parakeet kcmil • 556.5 (26/7) Dove kcmil • 556.5 (30/7) Eagle kcmil • 605 (24/7) Peacock kcmil • 605 (26/7) Squab kcmil • 605 (30/19) Teal kcmil • 636 (24/7) Rook kcmil • 636 (26/7) Grosbeak kcmil • 636 (30/19) Egret kcmil • 666.6 (24/7) Flamingo kcmil • 715.5 (54/7) Crow kcmil • 715.5 (24/7) Stilt kcmil • 715.5 (26/7) Starling kcmil • 715.5 (30/19) Redwing kcmil • 795 (54/7) Condor kcmil • 795 (26/7) Drake kcmil • 795 (30/19) Mallard kcmil • 874.5 (54/7) Crane kcmil • 900 (54/7) Canary kcmil
Conductor - ACSR Str Size Range	397.5 (30/7) Larkspur kcmil-900 (54/7) Canary kcmil

Configuration

Connector Type	Deadend
----------------	---------

Dimensions

Package Height	0.000 in
Dimension - Height mm	117.1 mm
Dimension - Hole Size fraction	1-1/4
Dimension - Height inch	4.61 in
Dimension - Height fraction	4-36/59 in
Dimension - B Length fraction	6-4/21 in
Package Weight	0.000 lb.

Dimension - Width mm	90 mm
Dimension - Width inch	3.56 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - Z inch	2.94 in
Dimension - L Length Overall mm	314 mm
Dimension - B Length inch	6.19 in
Dimension - Width fraction	3-14/25 in
Dimension - Hole Size mm	32 mm
Dimension - Hole Size inch	1.25 in
Dimension - Length Overall inch	12.38 in

General



A Hubbell brand

Plated	N
Material - Hardware	Galvanized Steel
UPC	781810013403
Prefilled Oxide Inhibitor	N
Material	Aluminum Alloy
Plating Type	Unplated
UPC 14 Digit GTIN	00781810013403

Logistics

Minimum Pack Quantity	8
Pallet Quantity	168
Carton Quantity	2

Product Assets

[Catalog \[English\]](#)