




DUW46, Deadend Strain Clamp, 1000-1500 kcmil Copper

By Burndy
Catalog # [DUW46](#)

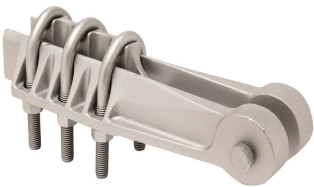

Cu Deadend Strain Clamp, 1000 - 1500 kcmil Cu

Features

- High strength, corrosion resistant copper alloy strain clamp
- Three silicon bronze U-bolts
- Single serrated saddle
- Galvanized steel clevis pin

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size Range	1000 kcmil-1500 kcmil
Conductor - Copper Str Size	• 1000 kcmil • 1250 kcmil • 1300 kcmil • 1500 kcmil

Configuration

Connector Type	Deadend
----------------	---------

Dimensions

Package Height	0.000 in
Dimension - Height mm	93 mm

Dimension - Height inch	3.66 in
Dimension - Height fraction	3-33/50 in
Dimension - B Length fraction	5-14/25 in
Package Weight	0.000 lb.
Dimension - Width mm	99 mm
Dimension - Width inch	3.91 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	294 mm
Dimension - B Length inch	5.56 in
Dimension - Width fraction	3-81/89 in
Dimension - Length Overall inch	11.59 in

General

Plated	Y
Material - Hardware	Galvanized Steel
UPC	781810013410
Material	Copper Alloy
Plating Type	Bright Dipped
UPC 14 Digit GTIN	00781810013410

Logistics

Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)