


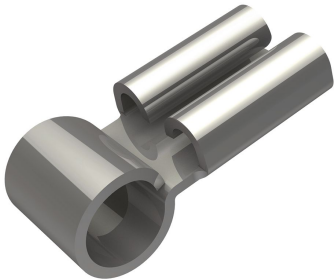

FL1025X03D, Flag Disconnect, 12 - 10 AWG, .25 x .03

By Burndy
Catalog # [FL1025X03D](#)

Uninsulated Flag-Style Quick Disconnect For 12 - 10 AWG (.25 x .03),
Dimpled Socket for Firm Grip



Features

- Flag-style female quick disconnects provide quick, reliable, snap-together interconnections without the use of tools
- Side entrance chamfer permits connections of 90° without bending the wire

Application

Female Disconnect

Specifications

Buy American Compliant	Contact Manufacturer
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	CM
Status	

Conductor

Conductor - Copper Str Size	• 12 AWG • 10 AWG
Conductor Size	12 - 10 AWG
Conductor Type	CU C Str-Size
Conductor - Copper Str Size Range	12 AWG-10 AWG

Configuration

Connector Type	Flag Female Quick Disconnect
----------------	------------------------------

Dimensions

Package Height	0.000 in
----------------	----------

Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Outside Diameter inch	0.23 in
Dimension - Strip Length inch	3/8 in
Dimension - B Length fraction	1/4 in
Dimension - Width mm	6 mm
Dimension - Width inch	0.25 in
Dimension - B Length inch	0.25 in
Dimension - Length Overall inch	0.63 in

General

Product Family	COMPRESSION
Trade Name	FINGRIP™
Plated	Yes
Sub Brand	FINGRIP
Product Type	Terminal
UPC	781810293638
Type	Disconnect Connectors
Material	Brass
Plating Type	Nickel
UPC 14 Digit GTIN	00781810293638

Logistics

Minimum Pack Quantity	50
Pallet Quantity	99999
Carton Quantity	600

Product Assets

[Catalog \[English\]](#)