




**FL1425X03D, Flag Female Disconnect, 16-14
AWG .25 x .03**

By Burndy
Catalog # [FL1425X03D](#)

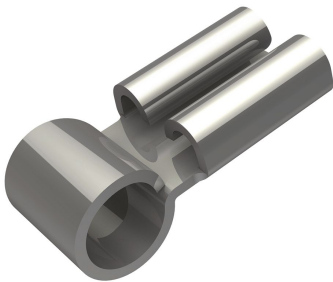

Uninsulated Flag Style Female Quick Disconnect For 16 - 14 AWG (.25 x .03), Dimpled Socket for Firm Grip

Features

- Flag-style female quick disconnects provide quick, reliable, snap-together interconnections without the use of tools
- Side entrance chamfer permits connections of 90° without bending the wire

Application

Female Disconnect

Specifications

Buy American Compliant	Contact Manufacturer
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL310
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor - Copper Str Size	• 16 AWG • 14 AWG
Conductor Size	16 - 14 AWG
Conductor Type	CU C Str-Size
Conductor - Copper Str Size Range	16 AWG - 14 AWG

Configuration

Connector Type	Flag Female Quick Disconnect
----------------	------------------------------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Outside Diameter inch	0.15 in
Dimension - Strip Length inch	3/8 in
Dimension - B Length fraction	1/4 in
Dimension - Width mm	6 mm
Dimension - Width inch	0.25 in
Dimension - B Length inch	0.25 in
Dimension - Length Overall inch	0.51 in

General

Product Family	COMPRESSION
Trade Name	FINGRIP™
Plated	Yes
Sub Brand	FINGRIP
Product Type	Terminal
UPC	781810297346
Type	Disconnect Connectors
Material	Brass
Plating Type	Tin
UPC 12 Digit	781810297346
UPC 14 Digit GTIN	00781810297346

Logistics

Minimum Pack Quantity	100
Pallet Quantity	99999
Carton Quantity	1200

Product Assets

[Catalog \[English\]](#)