




FL1825X03B, Uninsulated Flag Style Female Quick Disconnect For 22 - 18 AWG (.25 x .03)

By Burndy
Catalog # [FL1825X03B](#)

Uninsulated Flag Style Female Quick Disconnect For 22 - 18 AWG
(.25 x .03)

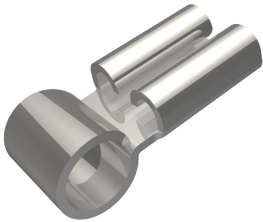

Features

- Flag-style female quick disconnects provide quick, reliable, snap-together interconnections without the use of tools
- Side entrance chamfer permits connections of 90° without bending the wire

Specifications

Certification - cULus	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - Industry Standards Met	UL310
Standards - RoHS Compliance Status	CM
Industry Standard(s)	UL467
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	22 - 18 AWG
Conductor - Copper Str Size	• 20 AWG • 18 AWG
Conductor - Copper Str Size Range	20 AWG - 18 AWG
Conductor Type	CU C Str-Size

Configuration

Connector Type	Flag Female Quick Disconnect
----------------	------------------------------

Dimensions

Dimension - Width inch	0.25 in
Dimension - Width mm	6 mm
Dimension - B Length fraction	1/4 in
Dimension - B Length inch	0.25 in
Dimension - Outside Diameter inch	0.13 in
Dimension - Length Overall inch	0.50 in

General

Trade Name	FINGRIP™
Plated	Y
Type	Disconnect Connectors
UPC 12 Digit	781810327845
UPC 14 Digit GTIN	00781810327845
Material	Brass
Plating Type	Tin
UPC	781810327845

Logistics

Minimum Pack Quantity	1000
Carton Quantity	1000
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)