




FLN1425X03D, Nylon Flag-Style Quick Disconnect For 16 - 14 AWG (.25 x .03)

By Burndy
Catalog # [FLN1425X03D](#)

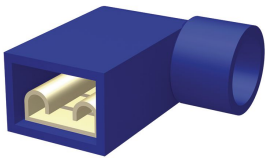

Nylon Flag-Style Quick Disconnect For 16 - 14 AWG (.25 x .03)

Features

- Flag-style female quick disconnects provide quick, reliable, snap-together interconnections without the use of tools
- Side entrance chamfer permits connections of 90° without bending the wire
- Dimpled female socket detent ensures firm grip

Application

Female Disconnect

Specifications

Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	16 - 14 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size
Conductor Range	#16 AWG to #14 AWG

Configuration

Connector Type	Flag Female Quick Disconnect
----------------	------------------------------

Dimensions

Package Length	0.000 in
Package Width	0.000 in
Package Weight	0.000 lb.
Package Height	0.000 in
Dimension - Strip Length inch	3/8 in
Dimension - Width inch	0.25 in
Dimension - Width mm	6 mm
Dimension - B Length inch	0.40 in

General

Insulation Type	Nylon
Trade Name	FINGRIP™
Insulation	Y
Sub Brand	HYDENT
Plated	Y
Type	Disconnect Connectors
UPC 12 Digit	781810525623
UPC 14 Digit GTIN	00781810525623
Material	Brass
Plating Type	Tin
UPC	781810525623

Logistics

Minimum Pack Quantity	50
Carton Quantity	600
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)