




FLN1825X03D, Nylon Flag-Style Quick Disconnect For 22 - 18 AWG (.25 x .03)

By Burndy
Catalog # [FLN1825X03D](#)

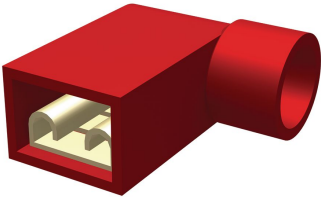

Nylon Flag-Style Quick Disconnect For 22 - 18 AWG (.25 x .03)

Features

- Flag-style female quick disconnects provide quick, reliable, snap-together interconnections without the use of tools
- Side entrance chamfer permits connections of 90° without bending the wire
- Dimpled female socket detent ensures firm grip

Specifications

Certification - cULus	Yes
Certification - UL Recognized	No
Certification - ETL	No
Standards - Industry Standards Met	UL310
Standards - RoHS Compliance Status	CM
Certification - CSA Approved	No
UL Listed	No

Conductor

Conductor Size	22 - 18 AWG
Conductor Type	CU C Str-Size
Conductor Range	#22 AWG to #18 AWG

Configuration

Connector Type	Flag Female Quick Disconnect
----------------	------------------------------

Dimensions

Dimension - Width inch	0.25 in
Package Length	0.000 in
Dimension - Width mm	6 mm
Package Width	0.000 in
Package Weight	0.000 lb.
Dimension - B Length inch	0.40 in
Package Height	0.000 in
Dimension - Strip Length inch	3/8 in

General

Insulation Type	Nylon
Trade Name	FINGRIP™
Plated	Y
Insulation	Y
Type	Disconnect Connectors
UPC 12 Digit	781810563243
UPC 14 Digit GTIN	00781810563243
Material	Brass
Plating Type	Tin
UPC	781810563243

Logistics

Minimum Pack Quantity	50
Carton Quantity	600
Pallet Quantity	99999

Product Assets

[Catalog \[English\]](#)