




FQN10M25X03D, Nylon Male Disconnect, 12-10 AWG (.25 x .03)

By Burndy
Catalog # [FQN10M25X03D](#)

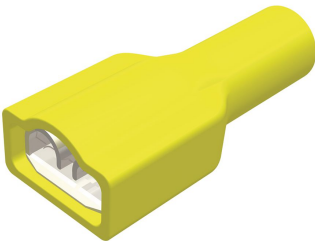

Fully Insulated Nylon Male Quick Disconnect For 12 - 10 AWG (.25 x .03)

Features

- Fully insulated connectors eliminate the need for post installation insulation
- Funnel entry barrel opening for quick and easy wire insertion
- Dimpled female socket detent for a firm grip

Application

For quickly connecting or disconnecting a terminal

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL310
Standards - RoHS Compliance	CM
Status	
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Size	12 AWG 10 AWG
Conductor Size	12 - 10 AWG
Conductor Type	CU C Str-Size
Conductor - Copper Str Size Range	12 AWG-10 AWG

Configuration

Connector Type	Male Quick Disconnect
----------------	-----------------------

Current

Voltage - Maximum	300 V
-------------------	-------

Dimensions

Package Height	0.000 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - Strip Length inch	3/8 in
Dimension - Width mm	6 mm
Dimension - Width inch	0.25 in
Dimension - Length Overall inch	0.96 in

General

Product Family	COMPRESSION
Insulation Type	Nylon
Trade Name	FINGRIP™
Insulation	Y
Plated	Yes
Sub Brand	FINGRIP
Product Type	Terminal
UPC	781810293041
Type	Disconnect Connectors
Material	Brass
Plating Type	Tin
UPC 12 Digit	781810293041
UPC 14 Digit GTIN	00781810293041

Logistics

Minimum Pack Quantity	25
Pallet Quantity	36000
Carton Quantity	300

Product Assets

[Catalog \[English\]](#)