



GAR1726, Mech Grounding Connector, Cable to Rod or Pipe

By Burndy
Catalog # [GAR1726](#)

Mechanical Grounding Connector, Cable to Rod or Pipe, 4 AWG
(Sol)-2/0 AWG (Str), 1-1/2" Pipe, 1-5/8"-1-7/8" Rod

Features

- Parallel or 90° Copper Cable Connection
- One-wrench installation
- Rated for Direct Burial in earth or concrete

Application


For Joining A Range Of Cable, Parallel Or At Right Angles To Rod Or Tube, Direct Burial Cable, Fence Post

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
Buy America(n) Qualified	• Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	EX
Status	
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Pipe or Round Tube Size Range	1-1/2 in
Conductor - Rod Size Range	1 5/8 in-1 7/8 in
Conductor - Copper Str Size	2/0 AWG
Conductor - Rod Size	1.620-1.90 in
Conductor - Copper Solid Size	4 AWG
Conductor - Copper Solid Size Range	4 AWG-3/0 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size • CU Tube Std-Size • Rod-Size
Conductor - Copper Str Size Range	5 AWG - 2/0 AWG
Conductor - Copper Tube Std Size Range	1 1/2 IPS IPS
Conductor - Copper Tube Std Size	1 1/2 IPS IPS

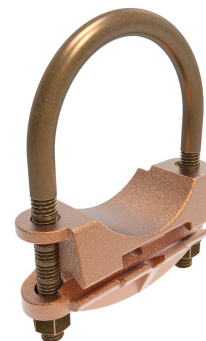

Dimensions

Package Height	0.000 in
Dimension - Height mm	101.6 mm
Dimension - Height inch	4.00 in
Dimension - Height fraction	4 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	40 mm
Dimension - Outside Diameter inch	1.90 in
Dimension - Width fraction	3-1/4 in
Dimension - Width mm	83 mm
Dimension - Width inch	3.25 in
Dimension - B Length inch	2.31 in
Dimension - Length Overall inch	1.56 in

Force Related

Installation Torque Recommended in-lb	240 LBS/in
Installation Torque Recommended Run in-lb	240 Lb in

General

Product Family	Grounding and Bonding Connectors>Copper Mechanical Grounding Connectors>Cable(s) to Ground Rod/Pipe/Tube (GAR/GD/GK)>Single Conductor(GAR)
Material - Hardware Plated	DURIUM™ Silicon Bronze
Sub Brand	No
Product Type	MECHANICAL CONNECTOR
UPC	781810234204
Type	GAR
U Bolt Type	268
Material	Copper
Plating Type	Bright Dipped
UPC 12 Digit	781810234204
UPC 14 Digit GTIN	00781810234204

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1800
Carton Quantity	30



A Hubbell brand