


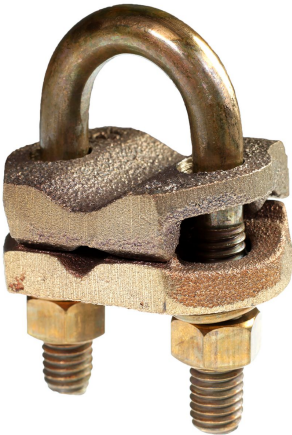

GAR6426SE, Mechanical Ground Conn, Cable to Rod or Pipe

By Burndy
Catalog # [GAR6426SE](#)

Mechanical Grounding Connector, 4 Sol - 2/0 Str; Pipe Size: 3/8" IPS; Rod Size: 5/8" - 3/4" with split lock washers; Direct Burial



Features

- Mechanical Ground Connector
- 4 Sol-2/0 Str
- 3/8" IPC, 5/8"-3/4" Rod
- Supplied with split lock washers
- Direct Burial

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - RoHS Compliance	EX
Status	
Certification - cULus	No
Buy America(n) Qualified	Contact Manufacturer
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Pipe or Round	3/8 in
Tube Size	
Conductor - Copper Solid Size	4 AWG-2/0 AWG
Range	
Conductor - Rod Size	0.625in - 0.75in

Dimensions

Package Height	0.000 in
Dimension - Height mm	38 mm
Dimension - Height inch	1.50 in

Package Weight	0.000 lb.
Dimension - Width mm	52 mm
Dimension - Width inch	2.06 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall	40 mm
mm	
Dimension - Length Overall	1.56 in
inch	

Force Related

Installation Torque	240 lb-in
Recommended in-lb	

General

Plated	N
UPC	781810503973
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810503973
UPC 14 Digit GTIN	00781810503973

Logistics

Minimum Pack Quantity	500
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)