



GB26, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GB26](#)

Mechanical Grounding Connector, Cable to 1/4" Thick Bar, 4 AWG (Sol)-2/0 AWG (Str), 3/8" Stud, 1-1/2 IN Width

Features

- High copper alloy ground connector for joining a range of cable to 1/4" thick bar
- Type GB separates cable from bar
- One-wrench installation
- UL467 Listed
- Suitable for Direct Burial in earth or concrete

Application


For Copper Cable To Bar, Direct Burial Cable

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - cULus	No
EU RoHS Indicator	Yes
Certification - UL Listed Direct Burial	Yes
Industry Standard(s)	UL467
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor - Copper Solid Size Range	4 AWG-2/0 AWG
Conductor - Copper Str Size Range	4 AWG-2/0 AWG
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG

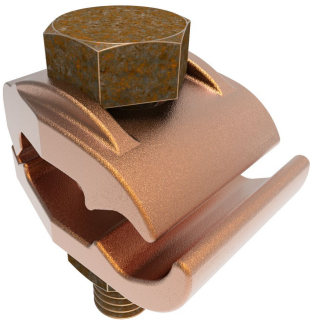

- 1 AWG
- 1/0
- 2/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	44.2 mm
Dimension - Height inch	1.74 in
Package Weight	0.000 lb.
Dimension - Width inch	1.42 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	24 mm
Dimension - Width fraction	1-3/7 in
Dimension - Length Overall inch	0.94 in

Force Related

Installation Torque	240 lb-in
Recommended in-lb	

General

Physical Attribute - Screw Type	Hexagonal Bolt
Plated	N
Sub Brand	MECHANICAL CONNECTOR
UPC	781810231210
Type	GB
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810231210
UPC 14 Digit GTIN	00781810231210

Logistics

Pallet Quantity	6250
Carton Quantity	25

Product Assets

[Catalog \[English\]](#)