




GB26OSB, Mechanical Grounding Connector, Cable to Bar

By Burndy
Catalog # [GB26OSB](#)

Mechanical Grounding Connector, Cable to 1/4" Thick Bar, 4 AWG (Sol)-2/0 AWG (Str), 3/8" Stud

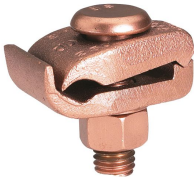

Features

- High copper alloy ground connector for joining a range of cable to 1/4" thick bar
- Type GB separates cable from bar
- Oval Shank Bolt
- Silicon Bronze Hardware
- Rated for Direct Burial in earth of concrete
- UL467

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	CM
Status	
Certification - cULus	No
Certification - UL Listed Direct Burial	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	UL467
UL Listed	No
Certification - CSA Approved	No

Conductor

Conductor - Copper Solid Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 AWG • 2/0 AWG
Conductor - Copper Solid Size Range	4 AWG-2/0 AWG
Conductor - Copper Str Size Range	4 AWG - 2/0 AWG
Conductor - Copper Str Size	• 4 AWG • 3 AWG • 2 AWG • 1 AWG

- 1/0
- 2/0 AWG

Dimensions

Package Height	0.000 in
Dimension - Height mm	44.2 mm
Dimension - Height inch	1.74 in
Package Weight	0.000 lb.
Dimension - Width inch	1.52 in
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	27 mm
Dimension - Width fraction	1-1/2 in
Dimension - Length Overall inch	0.94 in

Force Related

Installation Torque Recommended	240 lb-in in-lb
---------------------------------	-----------------

General

Physical Attribute - Screw Type	Oval Shank Bolt
Plated	N
UPC	781810059920
Material Type - Screw	DURIUM™ Silicon Bronze
Material	Copper Alloy
Plating Type	Unplated
UPC 12 Digit	781810059920
UPC 14 Digit GTIN	00781810059920

Logistics

Minimum Pack Quantity	25
Pallet Quantity	1
Carton Quantity	1

Product Assets

[Catalog \[English\]](#)